




Counterbored
for cap screw
DIN 912-M5 / M6

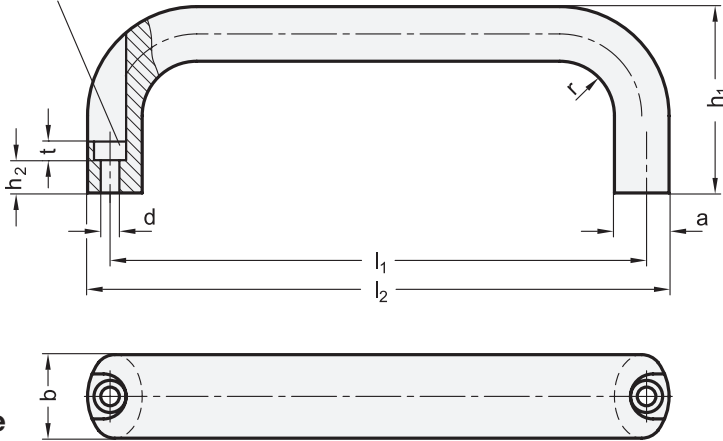

Universal table

Dimensions in: millimeters - inches

b	l ₁ ±0.25	a	d	h ₁	h ₂	l ₂	r	t
20 .79	100 3.94	13 .51	5.4 .21	49 1.93	13.5 .53	112 4.41	13 .51	5.5 .22
20 .79	112 4.41	13 .51	5.4 .21	49 1.93	13.5 .53	124 4.88	13 .51	5.5 .22
20 .79	120 4.72	13 .51	5.4 .21	51 2.01	13.5 .53	132 5.20	13 .51	5.5 .22
20 .79	128 5.04	13 .51	5.4 .21	51 2.01	13.5 .53	140 5.51	13 .51	5.5 .22
20 .79	160 6.30	13 .51	5.4 .21	51 2.01	13.5 .53	172 6.77	13 .51	5.5 .22
26 1.02	116 4.57	17 .67	6.4 .25	55 2.17	11 .43	130 5.12	17 .67	6 .24
26 1.02	120 4.72	17 .67	6.4 .25	55 2.17	11 .43	134 5.28	17 .67	6 .24
26 1.02	132 5.20	17 .67	6.4 .25	55 2.17	11 .43	146 5.75	17 .67	6 .24
26 1.02	164 6.46	17 .67	6.4 .25	57 2.24	11 .43	178 7.01	17 .67	6 .24
26 1.02	179 7.05	17 .67	6.4 .25	57 2.24	11 .43	193 7.60	17 .67	6 .24
26 1.02	196 7.72	17 .67	6.4 .25	57 2.24	11 .43	210 8.27	17 .67	6 .24

Specification

- Aluminum
 - Powder coated
 - Black, RAL 9005, textured finish
 - Black, RAL 9005, textured finish, UV-resistant
 - Red, RAL 3000, textured finish
 - Silver, RAL 9006, textured finish
 - Anodized, natural color
 - Blank, tumbled finish
- Both dimensions, inch and metric, are interchangeable
- RoHS compliant

- SW
- SWU
- RS
- SR
- EL
- BL

Information

GN 565.1 cabinet „U“ handles are made from a bent aluminum profile and have excellent stability and ergonomic design. Due to the production process, special designs (especially extra long versions) can be supplied even in relatively small quantities.

In addition to the standard finishes, these cabinet „U“ handles are also available with a functional coating: The SWU version is coated with a highly weather-resistant and UV-protective powder coating system, making this version excellent for outdoor use.

see also...

- Cabinet „U“ Handles GN 565.5 (Stainless Steel, Mounting from the Back or from the Operator's Side)
- T-Nut Assemblies GN 965 (for 30 / 40 mm T-Slot Profile Systems)
- T-Nut Assemblies GN 968 (for 30 / 40 / 45 mm T-Slot Profile Systems)

On request

- With certain minimum quantities, colors, lengths other than standard, especially extra long versions
- Various metric and inch size fasteners and kit packaging

How to order 1 2 3 GN 565.1-26-132-SW	1	Handle width b
	2	Length l ₁
	3	Finish